 


SMC Female Straight to SMC Female Straight Cable

Features

- 50 Ω Impedance
- DC - 12.4 GHz Frequency Range
- 750 V (RMS) Dielectric Withstanding Voltage
- 250 V (RMS) Working Voltage



ITEM#	\$	£	€	RMB	LENGTH
CA2736	\$ 43.60	£ 31.39	€ 37.93	¥ 347.49	36" (0.9 m)
CA2760	\$ 46.10	£ 33.19	€ 40.11	¥ 367.42	60" (1.5 m)




CA2736

Banana Patch Cords

Features

 - Stackable
- Available in Black or Red



Red Banana Patch Cords

ITEM #	\$	£	€	RMB	LENGTH
T13122	\$ 6.60	£ 4.75	€ 5.74	¥ 52.60	12" (0.3 m)
T13242	\$ 7.00	£ 5.04	€ 6.09	¥ 55.79	24" (0.6 m)


Black Banana Patch Cords

ITEM #	\$	£	€	RMB	LENGTH
T13120	\$ 6.60	£ 4.75	€ 5.74	¥ 52.60	12" (0.3 m)
T13240	\$ 7.00	£ 5.04	€ 6.09	¥ 55.79	24" (0.6 m)

USB 2.0A Male to USB 2.0A Female Cable

Features

- USB 2.0
- Hi-Speed 480 Mbps Transmission
- 28 Gauge Conductor

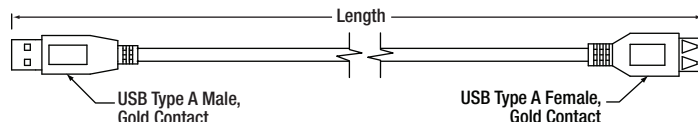


ITEM #	\$	£	€	RMB	LENGTH
USB-C-36	\$ 6.00	£ 4.32	€ 5.22	¥ 47.82	36" (0.9 m)
USB-C-72	\$ 6.90	£ 4.97	€ 6.00	¥ 54.99	72" (1.8 m)
USB-C-180	\$ 8.50	£ 6.12	€ 7.40	¥ 67.75	180" (4.6 m)

 **Mechanical**
Drawings Available on the
WEB

USB 2.0A Male to USB 2.0 Mini-B Male Cable

Features

- USB 2.0
- Compatible with T-Cube Controllers

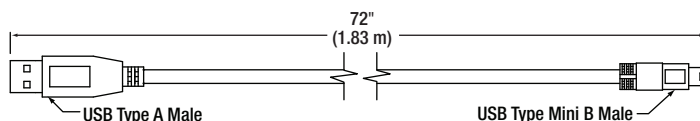


ITEM #	\$	£	€	RMB	LENGTH
USB-AB-72	\$ 8.00	£ 5.76	€ 6.96	¥ 63.76	72" (1.8 m)

USB 2.0A Male to USB 2.0B Male Cable

Features

- USB 2.0
- Double Cable Shielding
- Color May Change Without Notice

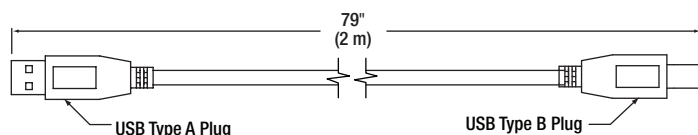

ITEM #	\$	£	€	RMB	LENGTH
USB-A-79	\$ 8.00	£ 5.76	€ 6.96	¥ 63.76	79" (2.0 m)

Please refer to our website for complete models and drawings.