
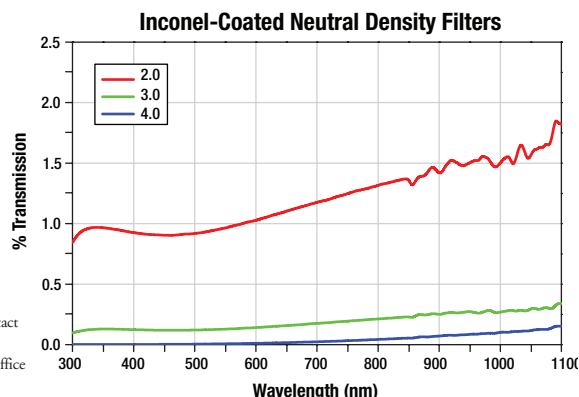


Mounted Reflective ND Filter Kits

- Includes OD=0.1, 0.2, 0.3, 0.4, 0.5, 0.6, 1.0, 2.0, 3.0, and 4.0 Filters
- Spectrally Flat Across Visible Wavelengths
- Inconel-Coated N-BK7 Substrate
- Clear Aperture: Ø0.89" (Ø22.5 mm)
- Mounted in Engraved SM1 Lens Tubes
- Optical Density Tolerance: $\pm 5\%$ @ 633 nm
- Scratch-Dig: 40-20

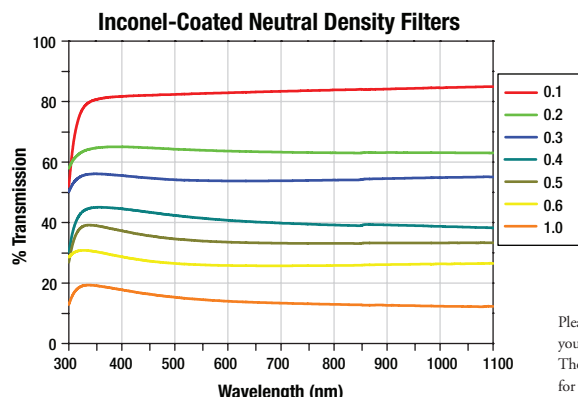



Please contact
your local
Thorlabs office
for custom
optical scans.

ITEM #	\$	£	€	RMB	DESCRIPTION
NDK01	\$ 611.75	£ 440.46	€ 532.22	¥ 4,875.65	Set of 10 SM1-Mounted Ø25.0 mm Reflective ND Filters

Mounted Reflective UV ND Filter Kits



- Includes OD=0.1, 0.2, 0.3, 0.4, 0.5, 0.6, 1.0, 2.0, 3.0, and 4.0 Filters
- Nickel-Coated UV Fused Silica Substrate
- Clear Aperture: Ø0.89" (Ø22.5 mm)
- Mounted in Engraved SM1 Lens Tubes
- Convenient Storage Case
- Optical Density Tolerance: $\pm 5\%$ @ 300 nm
- Scratch-Dig: 40-20

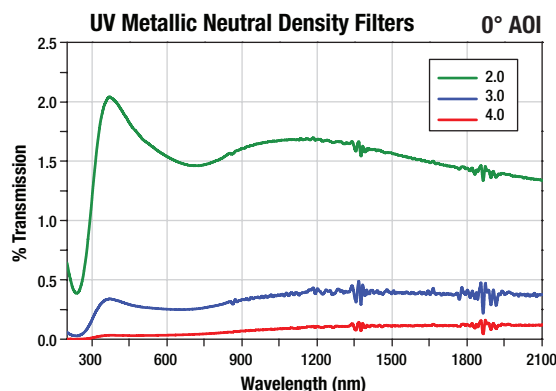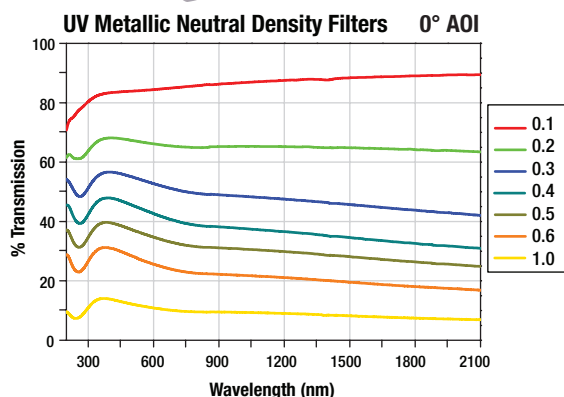

ITEM #	\$	£	€	RMB	DESCRIPTION
NUK01	\$ 620.73	£ 446.93	€ 540.04	¥ 4,947.22	Set of 10 SM1-Mounted Ø25.0 mm Reflective UV ND Filters