


For current pricing,
please see our website.

405 nm Adjustable Narrowband, 10 W

ITEM #	IO-5-405-LP
Type	Adjustable Narrowband
Center Wavelength	405 nm
Tuning Range	395 - 420 nm
Operating Range	390 - 425 nm
Transmission	84%
Typ. Isolation (Min)	36 dB (32 dB)
Max Beam Diameter	4.5 mm
Optical Axis Height*	0.88"
Max Power	10 W
Max Power Density	30 W/cm ²
Isolator OD x L**	Ø1.20" x 2.46"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

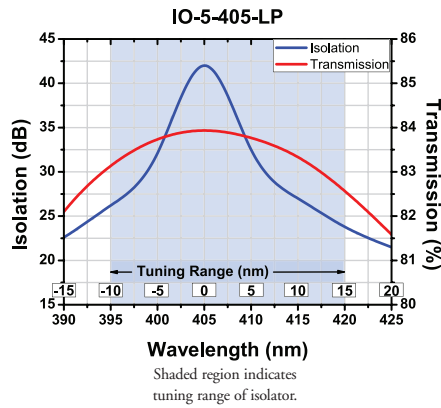

COMPATIBLE
WITH
SM1RC



IO-5-405-LP


ITEM #	\$	£	€	RMB	DESCRIPTION
IO-5-405-LP	\$ 1,975.00	£ 1,422.00	€ 1,718.25	¥ 15,740.75	405 nm Adjustable Narrowband Isolator, 10 W (Max) Power

532 nm Adjustable Narrowband, 3 W

ITEM #	IO-3-532-LP
Type	Adjustable Narrowband
Center Wavelength	532 nm
Tuning Range	522 - 543 nm
Operating Range	510 - 550 nm
Transmission	93%
Typ. Isolation (Min)	40 dB (35 dB)
Max Beam Diameter	2.7 mm
Optical Axis Height*	0.88"
Max Power	3 W
Max Power Density	100 W/cm ²
Isolator OD x L**	Ø1.20" x 2.46"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

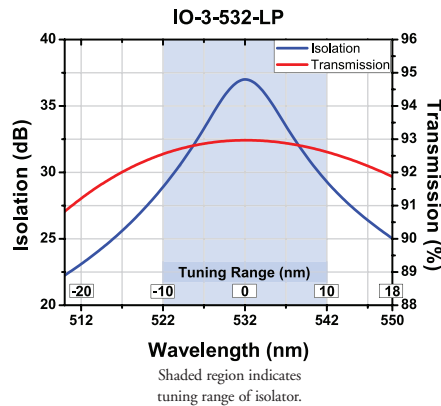

COMPATIBLE
WITH
SM1RC

NEW
product



IO-3-532-LP


ITEM #	\$	£	€	RMB	DESCRIPTION
IO-3-532-LP	\$ 1,565.00	£ 1,126.80	€ 1,361.55	¥ 12,473.05	532 nm Adjustable Narrowband Isolator, 3 W (Max) Power

532 nm Adjustable Narrowband, 40 W

ITEM #	IO-5-532-HP
Type	Adjustable Narrowband
Center Wavelength	532 nm
Tuning Range	522 - 543 nm
Operating Range	510 - 550 nm
Transmission	89%
Typ. Isolation (Min)	42 dB (38 dB)
Max Beam Diameter	4.7 mm
Optical Axis Height*	0.88"
Max Power	40 W
Max Power Density	500 W/cm ²
Isolator OD x L**	Ø1.20" x 3.26"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

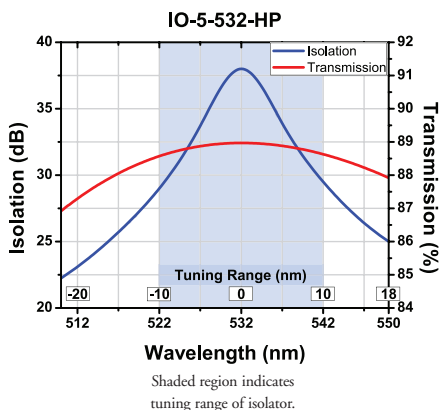

COMPATIBLE
WITH
SM1RC

NEW
product



IO-5-532-HP

ITEM #	\$	£	€	RMB	DESCRIPTION
IO-5-532-HP	\$ 1,900.00	£ 1,368.00	€ 1,653.00	¥ 15,143.00	532 nm Adjustable Narrowband Isolator, 40 W (Max) Power