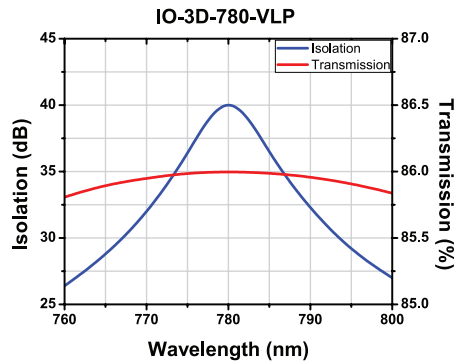


780 nm Fixed Narrowband, 0.7 W

ITEM #	IO-3D-780-VLP
Type	Fixed Narrowband
Center Wavelength	780 nm
Tuning Range	N/A
Operating Range	760 - 800 nm
Transmission	86%
Typ. Isolation (Min)	40 dB (34 dB)
Max Beam Diameter	2.7 mm
Optical Axis Height*	0.75"
Max Power	0.7 W
Max Power Density	25 W/cm ²
Isolator OD x L**	Ø0.87" x 1.25"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator



IO-3D-780-VLP
1.50" x 1.50" Base

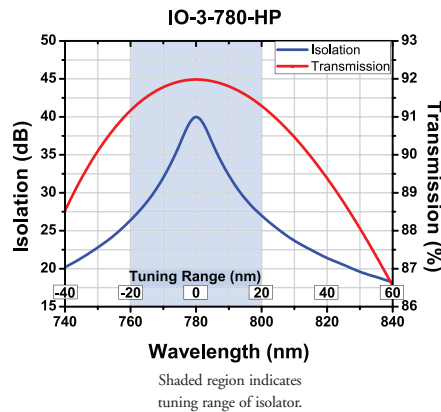
ITEM #	\$	£	€	RMB	DESCRIPTION
IO-3D-780-VLP	\$ 1,095.00	£ 788.40	€ 952,65	¥ 8,727.15	780 nm Fixed Narrowband Isolator, 0.7 W (Max) Power

780 nm Adjustable Narrowband, 15 W

ITEM #	IO-3-780-HP
Type	Adjustable Narrowband
Center Wavelength	780 nm
Tuning Range	760 - 800 nm
Operating Range	740 - 840 nm
Transmission	92%
Typ. Isolation (Min)	40 dB (34 dB)
Max Beam Diameter	2.7 mm
Optical Axis Height*	0.88"
Max Power	15 W
Max Power Density	500 W/cm ²
Isolator OD x L**	Ø1.20" x 3.76"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator


COMPATIBLE
WITH
SM1RC


IO-3-780-HP

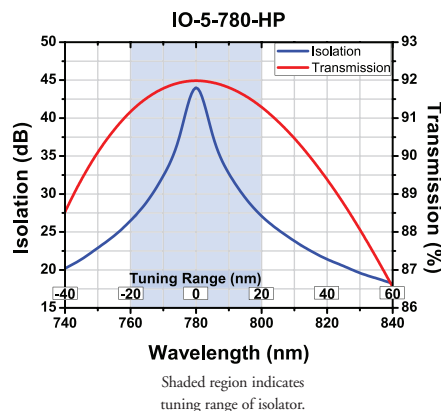
ITEM #	\$	£	€	RMB	DESCRIPTION
IO-3-780-HP	\$ 1,750.00	£ 1,260.00	€ 1,522,50	¥ 13,947.50	780 nm Adjustable Narrowband Isolator, 15 W (Max) Power

780 nm Adjustable Narrowband, 40 W

ITEM #	IO-5-780-HP
Type	Adjustable Narrowband
Center Wavelength	780 nm
Tuning Range	760 - 800 nm
Operating Range	740 - 840 nm
Transmission	92%
Typ. Isolation (Min)	44 dB (38 dB)
Max Beam Diameter	4.7 mm
Optical Axis Height*	0.88"
Max Power	40 W
Max Power Density	500 W/cm ²
Isolator OD x L**	Ø1.20" x 3.76"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator


COMPATIBLE
WITH
SM1RC


IO-5-780-HP

ITEM #	\$	£	€	RMB	DESCRIPTION
IO-5-780-HP	\$ 2,150.00	£ 1,548.00	€ 1,870,50	¥ 17,135.50	780 nm Adjustable Narrowband Isolator, 40 W (Max) Power

780 nm
Fiber
Isolators

See Page
1121