

HDPS24 - June 17, 2015

Item HDPS24 was discontinued on June 15, 2015. For informational purposes, this is a copy of the website content at that time and is valid only for the stated product.

56 Sparta Avenue • Newton, New Jersey 07860
 (973) 300-3000 Sales • (973) 300-3600 Fax
www.thorlabs.com



POWER CORDS AND STRIPS

- ▶ 6-, 12-, and 24-Outlet Power Strips with US-, EU-, and UK-Style Connectors
- ▶ Power Cords with US-Style Connectors
- ▶ Cable Racks


HDPS12-UK
 12-Outlet Surge-Protected
 Power Strip with
 UK-Style Connectors



SP620
 6-Outlet Surge-Protected
 Power Strip with US-Style
 (110 VAC) Connectors



T17251
 US-Style (110 VAC)
 Power Cord

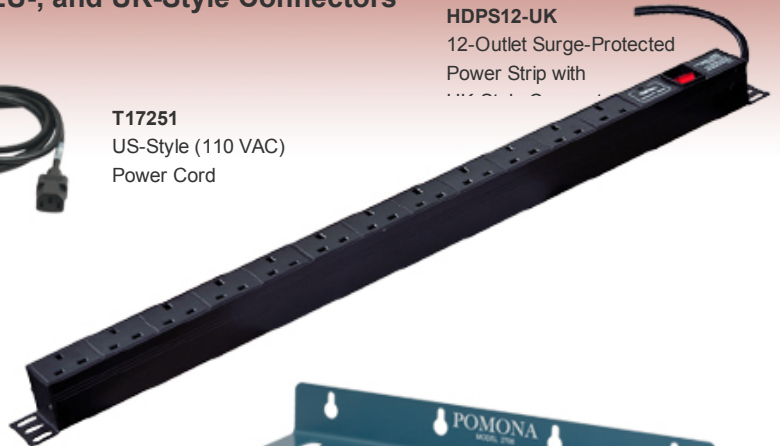

T1508
 14-Slot Wall-Mounted Cable Rack



T2708
 9-Slot Wall-Mounted Cable Rack


OVERVIEW

Thorlabs offers a selection of power cords, power strips, and cable racks to meet your needs. The T17251 power cord is 7.5' (2.3 m) long, has US-style connectors, and is sold in packs of 5. Additionally, we offer a 6-outlet power strip with US-style connectors, and 12-outlet and 24-outlet power strips with US-, EU-, or UK-style connectors. To view our selection of other cable types, please use the links to the right.

Cables and Cords Selection Guide

BNC Cables	Banana Cables
SMC Cables	Stepper Motor Cables
SMA Cables	Piezo Cables
USB Cables	Detector Power Cords

24-Outlet Power Strip - US, EU, or UK Plugs

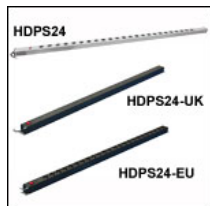

- ▶ 24-Outlet, Surge-Protected Power Strip
- ▶ Three Outlet Types: US, EU, or UK
- ▶ Electrically Grounded Outlets
- ▶ US Version has Built-In Circuit Breaker

These 24-outlet power strips are available with US-, EU-, and UK-style outlets. Each is designed for indoor use and is housed within an impact-resistant, sturdy metal case. The units are turned on and off using the built-in rocker switch. The US power strip offers a built-in circuit breaker. The US power strip is mounted using the supplied mounting clips, while the EU and UK power strips are fitted with clearance holes for standard M6 bolts.

Item #	HDPS24	HDPS24-EU	HDPS24-UK
Electrical			
Voltage Rating	120 VAC	230 VAC	240 VAC
Current Rating	15 A	16 A	13 A
Frequency	60 Hz	50 Hz	60 Hz
Power Rating	1800 W	3680 W	3120 W
Full Surge Protection	450 J	1.75 kA for 8/20 µsec	
Circuit Breaker	Yes	No	
EMI / RFI Filtering	Yes		
CE Approved	No	Yes	
UL Listed (C and US)	Surge Protective Device 6G99	No	
Physical			
Cord Length	6 Feet (1.82 m)	3 m (9.8')	
Cord Gauge	14 AWG	1.5 mm ²	
Number of Outlets	24		
Body Material	Aluminum		
Dimensions (L x W x H)	1829 x 51 x 44 mm (72" x 2" x 1.75")	1717 x 67.5 x 58.0 mm (67.6" x 2.66" x 2.28")	

Attention:

The power strips are designed for indoor use only. These devices should not be installed in wet or damp areas exposed to moisture. They are not recommended for use with aquariums. We do not recommend plugging one HDPS24 into another HDPS24 or similar surge-protecting device.



The HDPS24-UK Power Strip Installed on One of Our Optical Table Shelves

Part Number	Description	Price	Availability
HDPS24-EU	24-Outlet, Surge-Protected Power Strip, EU Plugs	\$170.00	Lead Time
HDPS24-UK	24-Outlet, Surge-Protected Power Strip, UK Plugs	\$160.00	2 Weeks
HDPS24	24-Outlet, Surge-Protected Power Strip, US Plugs	\$150.00	Today

Visit the *Power Cords and Strips* page for pricing and availability information:
http://www.thorlabs.com/newgrouppage9.cfm?objectgroup_id=2361