

▼ CHAPTERS

Fiber Patch
Cables

Bare Fiber

Fiber
OptomechanicsFiber
ComponentsTest and
Measurement

▼ SECTIONS

Collimators

Couplers

WDMs

RGB Combiner

Circulators

Fiber Isolators

Faraday Mirrors

Fiber Attenuators

Polarization
Controllers


Optical Switches

Mating Sleeves

Terminating
Connectors

Termination

SC Ceramic Fiber Connector

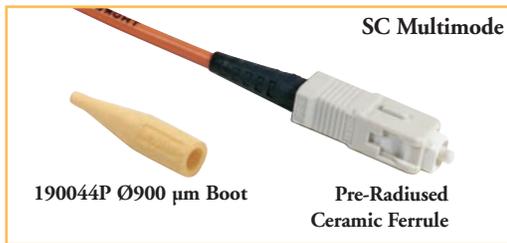

This SC-style connector features a pre-radiused (20 mm) ceramic ferrule that is packaged with a Ø3 mm boot and minimizes back reflections. The connector has a bore size of Ø125 µm. Each connector package includes a fiber connector cap and a Ø3 mm boot.


ITEM #	\$	£	€	RMB	DESCRIPTION
30126H1	\$ 8.67	£ 6.24	€ 7,54	¥ 69.10	SC, MM, Ø125 µm Bore
190044P	\$ 10.50	£ 7.56	€ 9,14	¥ 83.69	Ø900 µm Yellow Boots, 25/Pack

CT042 Crimp Tool is Required for Ø3 mm Tubing

SC Glue-On Connector for Plastic Optical Fiber

Features

- Standard SC Form Factor with Customized Ferrule
- All Material Complies with UL94 V0 and RoHS
- Internal Ferrule Dimension Allows for Direct Connection, No Buffer Removal Required
- F120 Fast Room Temperature Cure Epoxy Recommended for Termination
- LCP (Gray Plastic) Ferrule Material
- Compatible with Gradient-Index Plastic Optical Fiber (GIPOF), See Pages 1063 - 1064

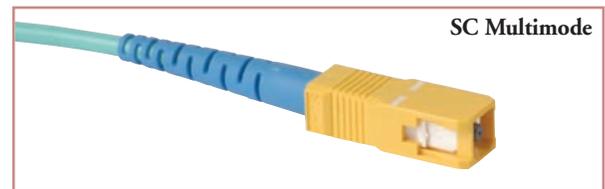

Crimp Tool CT042 Required for Ø3 mm Tubing

FERRULE DIMENSIONS	MIN	TYPICAL	MAX
Inner Diameter (ID)	0.493 mm	0.494 mm	0.496 mm

ITEM #	\$	£	€	RMB	DESCRIPTION
30500A1	\$ 6.85	£ 4.93	€ 5,96	¥ 54.59	SC Glue-On Connector

Bare Fiber Terminator



For applications where a temporary fiber termination is desired, our Bare Fiber Terminator is the solution. It is reusable and can be easily cleaned if the fiber breaks inside the connector by using the WC100 clean out wires (below). The bare fiber terminator is designed to mechanically hold fibers in standard connectors (sold separately). The BFTU accepts ferrules up to Ø0.158" (Ø4 mm) and fibers up to Ø0.03" (Ø0.7 mm).

The design is compatible with FC, ST, and SMA connectors, but is **not** compatible with the following connectors:

- SMA Connectors: 10850A, 11040A, 11050A, 11275A
- FC/PC Connectors: 30080D1, 301255D1
- FC/APC Connectors: 30126F1, 30126K1
- FC MM Connector: 30128E2, 30140E1, 30126G2 Series
- LC® SM Connector: 86024-5500

See Pages 1142 - 1143 for Compatible Connectors

ITEM #	\$	£	€	RMB	DESCRIPTION
BFTU	\$ 76.80	£ 55.30	€ 66,82	¥ 612.10	Terminator for FC, ST, and SMA Connectors
WC100	\$ 12.60	£ 9.07	€ 10,96	¥ 100.42	Clean Out Wires (8 Pieces/Vial)