


SM1-Threaded Mounted Near IR Achromatic Doublets

- Holds Ø25.4 mm Achromatic Doublets
- Cell Engraved with Part Number, Focal Length, and Coating

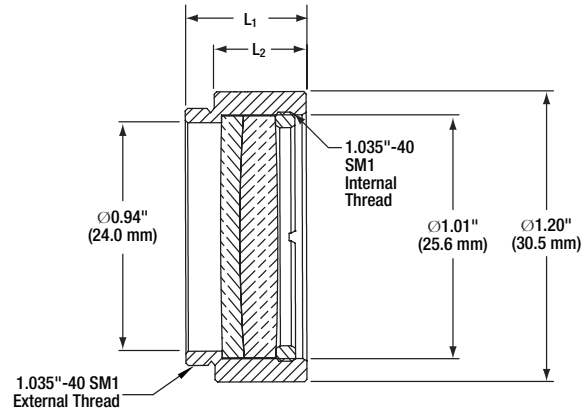


ITEM #	D* (mm)	f (mm)	L ₁ (mm)	L ₂ (mm)	MATERIALS	\$	£	€	RMB
AC254-030-B-ML	25.4	30	0.68	0.56	N-BAF10/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-035-B-ML	25.4	35	0.62	0.50	N-BAF10/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-040-B-ML	25.4	40	0.68	0.56	N-BAF10/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-045-B-ML	25.4	45	0.56	0.44	N-LAK22/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-050-B-ML	25.4	50	0.56	0.44	N-LAK22/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-060-B-ML	25.4	60	0.50	0.38	N-LAK22/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-075-B-ML	25.4	75	0.50	0.38	N-BAF10/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-100-B-ML	25.4	100	0.50	0.38	N-LAK22/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-150-B-ML	25.4	150	0.50	0.38	N-LAK22/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-200-B-ML	25.4	200	0.56	0.44	N-LAK22/SF10	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-250-B-ML	25.4	250	0.50	0.38	SF5/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-300-B-ML	25.4	300	0.50	0.38	SF5/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-400-B-ML	25.4	400	0.50	0.38	SF5/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91
AC254-500-B-ML	25.4	500	0.50	0.38	SF10/N-SF6HT	\$ 103.00	£ 74.16	€ 89.61	¥ 820.91

*Diameter of Unmounted Lens

SM2-Threaded Mounted Near IR Achromatic Doublets

- Holds Ø50.8 mm Achromatic Doublets
- Cell Engraved with Part Number, Focal Length, and Coating

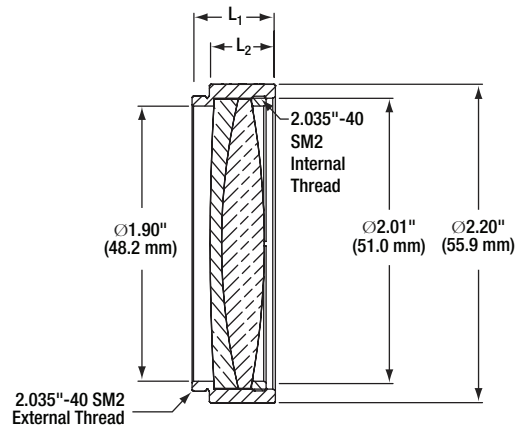

ITEM #	D* (mm)	f (mm)	L ₁ (mm)	L ₂ (mm)	MATERIALS	\$	£	€	RMB
AC508-075-B-ML	50.8	75	0.92	0.80	N-LAK22/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-080-B-ML	50.8	80	0.92	0.80	N-BAF10/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-100-B-ML	50.8	100	0.92	0.80	N-LAK22/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-150-B-ML	50.8	150	0.75	0.63	N-LAK22/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-200-B-ML	50.8	200	0.75	0.63	N-LAK22/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-250-B-ML	50.8	250	0.58	0.46	N-BAF10/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-300-B-ML	50.8	300	0.58	0.46	N-LAK22/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-400-B-ML	50.8	400	0.58	0.46	N-LAK22/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-500-B-ML	50.8	500	0.58	0.46	N-LAK22/N-SF6HT	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-750-B-ML	50.8	750	0.58	0.46	N-BAF10/SF10	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35
AC508-1000-B-ML	50.8	1000	0.58	0.46	N-BAF10/SF10	\$ 155.00	£ 111.60	€ 134.85	¥ 1,235.35

*Diameter of Unmounted Lens